


Safety at high speed

Improve the safety of your membrane filtration workflow

You don't have to be exposed to obvious risks every time you execute your microbiological analyses. Discover a safe and fast way of performing your membrane filtration with single-use EZ-Fit® Filtration Units.

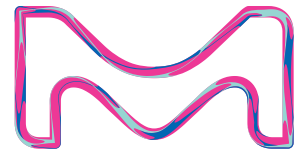

Filtration set-up with reusable funnels

Flaming for disinfection can lead to burns or blistering.

Be careful when installing the funnel on the manifold, you might clip your fingers.



Flaming
manifold head

5 sec



Flaming funnel
base and inside

4 sec



Cooling time with
sterile water

3 to 5 sec



Placing filter on
manifold head

5 sec



Installing filter
funnel on
manifold

3 sec




Filtration set-up with sterile single-use EZ-Fit® Filtration Units



EZ-Fit® Filtration Unit
set-up

1 sec

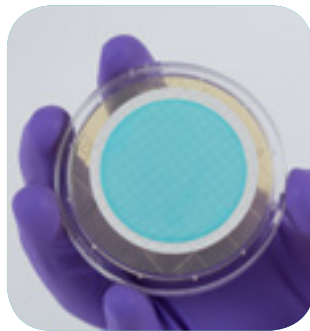

EZ-Fit® Filtration Units save you precious time while ensuring accurate results. The sterilized, disposable filtration devices for bioburden testing streamline your workflow.

Learn more:

EMDMillipore.com/EZ-Fit



For optimal microbial recovery, use EZ-Fit® Filtration Units with our Readyplate™ 55 plates. These 55 mm agar plates are small but mighty: the high filling volume ensures reproducible membrane transfer without bubbles and folds.

Learn more:

EMDMillipore.com/ReadyPlate55

EZ-Fit® Filtration Unit, blue base with pad

| Product Description | Pack Size | Cat. No. |
|------------------------------------------------------------------------------------------------|-----------|-----------|
| EZ-Fit® Filtration Unit, white membrane, 0.45µm pore size, 100 mL funnel, bulk packaging | 48 | EFHAW100B |
| EZ-Fit® Filtration Unit, white membrane, 0.45µm pore size, 100 mL funnel, individual packaging | 48 | EFHAW100I |
| EZ-Fit® Filtration Unit, white membrane, 0.45µm pore size, 250 mL funnel, bulk packaging | 48 | EFHAW250B |
| EZ-Fit® Filtration Unit, white membrane, 0.45µm pore size, 250 mL funnel, individual packaging | 48 | EFHAW250I |
| EZ-Fit® Filtration Unit, black membrane, 0.45µm pore size, 100 mL funnel, bulk packaging | 48 | EFHAB100B |
| EZ-Fit® Filtration Unit, black membrane, 0.45µm pore size, 100 mL funnel, individual packaging | 48 | EFHAB100I |
| EZ-Fit® Filtration Unit, black membrane, 0.45µm pore size, 100mL funnel, bulk packaging | 48 | EFHAB250B |
| EZ-Fit® Filtration Unit, black membrane, 0.45µm pore size, 250 mL funnel, individual packaging | 48 | EFHAB250I |



EZ-Fit® Filtration Unit, pink base

| Product Description | Pack Size | Cat. No. |
|--------------------------------------------------------------------------------------------------------|-----------|-----------|
| EZ-Fit® Filtration Unit, white membrane, 0.45µm pore size, 100 mL funnel, individual packaging, no pad | 48 | EFHVV10IS |
| EZ-Fit® Filtration Unit, white membrane, 0.45µm pore size, 100 mL funnel, multi packaging, no pad | 48 | EFHAW10MS |
| EZ-Fit® Filtration Unit, white membrane, 0.45µm pore size, 250 mL funnel, bulk packaging, no pad | 48 | EFHAW25BS |
| EZ-Fit® Filtration Unit, black membrane, 0.45µm pore size, 100 mL funnel, multi packaging, no pad | 48 | EFHAB10MS |
| EZ-Fit® Filtration Unit, black membrane, 0.45µm pore size, 250 mL funnel, bulk packaging, no pad | 48 | EFHAB25BS |
| EZ-Fit® Filtration Unit, white membrane, 0.22µm pore size, 100 mL funnel, multi packaging, no pad | 48 | EFGSW10MS |
| EZ-Fit® Filtration Unit, white membrane, 0.22µm pore size, 100 mL funnel, individual packaging, no pad | 48 | EFGSW10IS |
| EZ-Fit® Filtration Unit, white membrane, 0.8µm pore size, 100 mL funnel, bulk packaging, no pad | 48 | EFAAW10BS |
| EZ-Fit® Filtration Unit, white membrane, 0.8µm pore size, 250 mL funnel, bulk packaging, no pad | 48 | EFAAW25BS |
| EZ-Fit® Filtration Unit, black membrane, 0.8µm pore size, 100 mL funnel, bulk packaging, no pad | 48 | EFAAB10BS |
| EZ-Fit® Filtration Unit, black membrane, 0.8µm pore size, 250 mL funnel, bulk packaging, no pad | 48 | EFAAB25BS |



EZ Family

| Product Description | Pack Size | Cat. No. |
|---------------------------------------------------------------------|-----------|------------|
| EZ-Stream® Vacuum Pump for liquid transfer | 1 | EZSTREAM1 |
| 5 meters autoclavable silicone tubing with 9.5 mm internal diameter | 1 | STREAMTUB |
| EZ-Fit® Manifold, 1-place for EZ-Fit® Filtration Units | 1 | EZFITEFUN1 |
| EZ-Fit® Manifold, 3-place for EZ-Fit® Filtration Units | 1 | EZFITEFUN3 |
| EZ-Fit® Manifold, 6-place for EZ-Fit® Filtration Units | 1 | EZFITEFUN6 |
| EZ-Fit® filtration head for EZ-Fit® Filtration Units | 1 | EZFITMVHE1 |
| EZ-Fit® filtration head for EZ-Fit® Filtration Units | 3 | EZFITMVHE3 |
| EZ-Fit® filtration head gasket | 1 | EZFITMVG3 |



ReadyPlate™ 55 agar plates

| Product Description | Pack Size | Cat. No. |
|--------------------------------------------------|-----------|------------|
| ReadyPlate™ 55 CCA ISO 9308 | 20x55mm | 1467570020 |
| ReadyPlate™ 55 CCA ISO 9308 | 20x55mm | 1467570200 |
| ReadyPlate™ 55 Lactose TTC Agar | 20x55mm | 1467590020 |
| ReadyPlate™ 55 TGE Agar | 20x55mm | 1467610020 |
| ReadyPlate™ 55 Plate Count Agar | 20x55mm | 1467630020 |
| ReadyPlate™ 55 Slanetz and Bartley Agar ISO 7899 | 20x55mm | 1467650020 |
| ReadyPlate™ 55 CN Agar ISO 16266 | 20x55mm | 1467670020 |
| ReadyPlate™ 55 m-Green Agar | 20x55mm | 1467690020 |



To place an order or receive technical assistance in the U.S. and Canada, call toll-free 1-800-645-5476

For other countries across Europe and the world, please visit: EMDMillipore.com/offices

For Technical Service, please visit: EMDMillipore.com/techservice

